







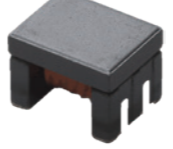

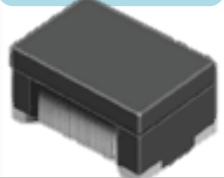



MURATA CMCC products application list and supported products

For Signal line - Automotive Grade -

Signal speed

(inch/mm)	Differential Signal										PoC*2
	CAN/ Flex Ray (-10Mbps)	CAN-FD (-8Mbps) DCMR Class3	A2B® (50Mbps)	Ethernet 100Base-T1 (100Mbps)	USB 2.0 (480Mbps)	Ethernet 1000Base-T1 (1000Mbps)	LVDS*1 (-1.5Gbps)	HDMI 1.4 (1.7Gbps)	HDMI 2.0 (6Gbps)	USB 3.1 (-10Gbps)	LVDS*1 (-6Gbps)
1.25 x 1.0mm (0504/1210)					DLM11SN _HZ2 Series 		DLM11SN _HZ2 Series 				
2.0 x 1.2mm (0805/2012)					NEW DLW21SH 900HQ2 		NEW DLW21SH _HQ2 Series 	NEW DLW21SH900HQ2 		NEW DLW21SH 391XQ2 DLW21PH 201XQ2	
3.2 x 2.5mm (1210/3225)		DLW32SH 101XF2 	DLW32MH 101XK2 	DLW32MH 201XK2 		DLW32MH 101XT2 				NEW 	
4.5 x 3.2mm (1812/4532)	DLW43SH Series 			DLW43MH 201XK2 							

*1 : Ser Des *2 : Power over Coax